


35RS Two Hole Retainer Strap

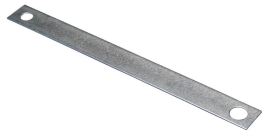

FEATURES

Retainer strap for beam clamps

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel


Table 1/1

Catalog Number	Length (L)	Width (W)	Flange Width	Rod Size 1 (RS1)	Rod Size 2 (RS2)
035RS0800EG	203.2mm	24.1 mm	150 mm Max	11.1	14.3
035RS1000EG	254mm	24.1 mm	200 mm Max	11.1	14.3
035RS1400EG	355.6mm	24.1 mm	300 mm Max	11.1	14.3
035RS1200EG	304.8mm	24.1 mm	250 mm Max	11.1	14.3
035RS1600EG	406.4mm	24.1 mm	355 mm Max	11.1	14.3
035RS0600EG	152.4mm	24.1 mm	100 mm Max	11.1	14.3
035RS1800EG	457.2mm	24.1 mm	406 mm Max	11.1	14.3

ADDITIONAL PRODUCT DETAILS

Field bend and use jam nut over hanger rod to secure.

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

