

Bolt Close Conduit/Pipe Clamp



CERTIFICATIONS



FEATURES

Retained bolt and built-in nut means there are less parts to handle or drop

Combo head bolt works with slotted, hex, #3 phillips or #2 robertson drivers

SPECIFICATIONS


Nut Type: Built-In Nut
Finish: Electrogalvanized
Material: Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Hole Size (HS)	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
CD2B	181150	25 - 33 mm	7.14 mm	880N	220N	cUL, UL
CD0B	181140	17 - 22 mm	7.14 mm	880N	220N	UL, cUL
CD3B	181380	36 - 43 mm	7.14 mm	880N	220N	UL, cUL, ITB

CatalogNumber	Article Number	Outer Diameter (OD)	Hole Size (HS)	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
CD1B	181190	19 - 25 mm	7.14 mm	880N	220N	cUL, ITB, UL
CD4B	181390	45 - 48 mm	7.14 mm	880N	220N	cUL, ITB, UL

DIAGRAMS

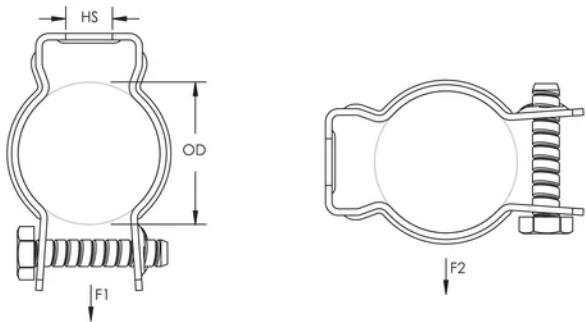

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

