

CLS Two Hole Shallow Saddle for Steel Pipe



FEATURES

Light duty support for steel pipe

Attaches directly to horizontal or vertical wall

Supports pipe close to wall or ceiling

SPECIFICATIONS

Finish: Electrogalvanized


Table 1/2

Catalog Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Length (L)	Width (W)	Thickness (T)
CLS50	50	60.3 mm	8 mm	84mm	25 mm	1.6 mm
CLS40	40	48.3 mm	8 mm	79mm	25 mm	1.6 mm
CLS25	25	33.7 mm	8 mm	69mm	25 mm	1.6 mm
CLS32	32	42.3 mm	8 mm	74mm	25 mm	1.6 mm
CLS65	65	76.1 mm	8 mm	125mm	30 mm	2 mm

Table 2/2

Catalog Number	Static Load
CLS50	1500N
CLS40	1500N
CLS25	1500N
CLS32	1500N
CLS65	1500N

DIAGRAMS

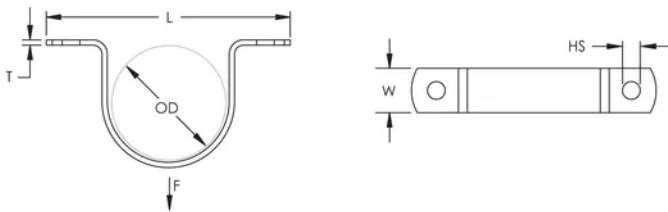

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

