

EA Slotted Framing Angle, Equal Leg



FEATURES

Cold formed, slotted

Slotted angle bracket for light-medium applications

For efficiently constructing fire pipe or HVAC ducting routes

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Length (L)	Height (H)	Width (W)	Thickness (T)	A	B
EA3030	3000mm	30 mm	30 mm	2.5 mm	27 mm	11.5 mm
EA5050	3000mm	50 mm	50 mm	4.7 mm	50 mm	19.5 mm

Table 2/2

Catalog Number	X
EA3030	11 x 18 mm
EA5050	14 x 30 mm

DIAGRAMS

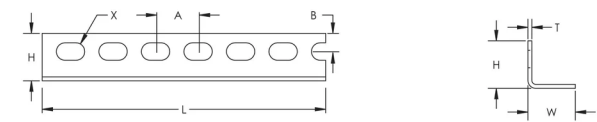

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

