

Easy Universal Sway Brace



CERTIFICATIONS



FEATURES

Use for both lateral and longitudinal sway brace applications

Unique slotted holes provide for easy slip-on installation eliminating loose hardware

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Meets NFPA®-13 requirements for seismic sway bracing

SPECIFICATIONS

Material: Steel;Cast Iron

Finish: Electrogalvanized

Table 1/1

Catalog Number	Article Number	NB/DN	A	B	Certifications
----------------	----------------	-------	---	---	----------------


CSBEZU0100EG	404356	25	174.6 mm	25.4 mm	cUL, AON Fire Protection, Rigid Seismic, UL, OSHPD
CSBEZU0125EG	404357	32	187.4 mm	25.4 mm	AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL
CSBEZU0150EG	404358	40	196.9 mm	25.4 mm	Korea Fire Institute, Rigid Seismic, ENG, AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL
CSBEZU0200EG	404359	50	206.4 mm	30.2 mm	Korea Fire Institute, Rigid Seismic, ENG, AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL
CSBEZU0250EG	404360	65	225.4 mm	30.2 mm	AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL
CSBEZU0300EG	404361	80	238.1 mm	30.2 mm	cUL, Korea Fire Institute, Rigid Seismic, ENG, AON Fire Protection, Rigid Seismic, UL, OSHPD
CSBEZU0400EG	404362	100	269.9 mm	38.1 mm	AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL, Korea Fire Institute, Rigid Seismic, ENG
CSBEZU0500EG	404363	125	308 mm	38.1 mm	AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL, Korea Fire Institute, Rigid Seismic, ENG

CSBEZU0600EG	404364	150	346.1 mm	50.8 mm	Korea Fire Institute, Rigid Seismic, ENG, AON Fire Protection, Rigid Seismic, UL, OSHPD, cUL
--------------	--------	-----	----------	---------	--

UL Loads (Listed for Restraints)		
Part Number	Lateral Sch 10 Service Pipe	Longitudinal Sch 40 Service Pipe
CSBEZU0100EG	2914 N	2914 N
CSBEZU0125EG	2914 N	2914 N
CSBEZU0150EG	2914 N	2914 N
CSBEZU0200EG	2914 N	NA

UL Loads (Listed for Sway Braces)			
Part Number	Lateral	Longitudinal	Brace Member
	KS D 3507/KS D 3562 Service Pipe	KS D 3507/KS D 3562 Service Pipe	
CSBEZU0200	5338 N	N/A	25A to 32A KS D 3562
CSBEZU0300	7117 N	3025 N	25A to 32A KS D 3562
CSBEZU0400	8896 N	4448 N	25A to 32A KS D 3562
CSBEZU0500	8896 N	4849 N	25A to 32A KS D 3562
CSBEZU0600	8896 N	4849 N	25A to 32A KS D 3562

DIAGRAMS

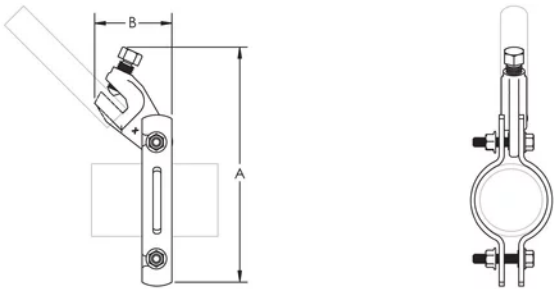

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

