

H-Ti/T Rod to Flange Clip



CERTIFICATIONS



FEATURES

Suspends threaded rod from beam flanges

Threaded rod hanger can swivel to provide a vertical dropdown

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Static Load
6TI24	10 mm	Threaded	3.2 - 6.4 mm	885N
4TI24	6 mm	Threaded	3.2 - 6.4 mm	885N
4TI912	6.4 mm	Threaded	14.3 - 19 mm	880N

Catalog Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Static Load
4TI58	6 mm	Threaded	7.9 - 12.7 mm	885N
6TI58	10 mm	Threaded	7.9 - 12.7 mm	885N
6TI912	10 mm	Threaded	14.3 - 19.1 mm	885N

DIAGRAMS

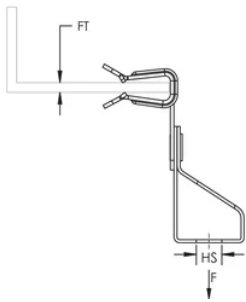

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

