

Hammer-On Flange Clip, Side Mount



CERTIFICATIONS



FEATURES

Provides an attachment for wire, S-hooks, chain, nVent CADDY Speed Link or other assemblies to flanges and profiles

Fits most beams

Installs with just a hammer

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Static Load
2H4	170010	Spring Steel	nVent CADDY Armour	2 - 3 mm	7.1 mm	700N
4H24S1	179610	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	7.1 mm	650N
4H24	170020	Spring Steel	nVent CADDY Armour	3 - 8 mm	7.1 mm	900N
4H58	170030	Spring Steel	nVent CADDY Armour	8 - 14 mm	7.1 mm	900N

CatalogNumber	Article Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Static Load
4H912	170040	Spring Steel	nVent CADDY Armour	14 - 20 mm	7.1 mm	900N
4H912S1	179630	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	7.1 mm	650N
4H58S1	179620	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	7.1 mm	650N

Table 2/2

Catalog Number	Article Number	Certifications
2H4	170010	ITB, UL, cUL
4H24S1	179610	
4H24	170020	cUL, CE, 4H, EM, EBC, ITB, UL
4H58	170030	CE, 4H, EM, EBC, ITB, UL, cUL
4H912	170040	CE, 4H, EM, EBC, cUL, ITB, UL
4H912S1	179630	
4H58S1	179620	

DIAGRAMS

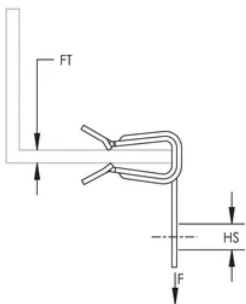

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

