

Medium Duty Pipe Clamp for Steel Pipe



FEATURES

For fastening of horizontal and vertical pipe services

Double bolted

Nuts and bolts included

Medium Duty

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Material: Steel


Table 1/2

Catalog Number	NB/DN	Outer Diameter (OD)	A	Screw Diameter (Sc)	Screw Length (L)	Thickness (T)
ERIC16114	100	113.3 mm	204 mm	12	40mm	6 mm
ERIC16165	150	165.1 mm	236 mm	12	40mm	6 mm
ERIC16220	200	219 mm	331 mm	12	40mm	6 mm
ERIC16273	250	273 mm	384 mm	12	50mm	6 mm
ERIC16324	300	323.9 mm	440 mm	12	50mm	6 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	A	ScrewDiameter (Sc)	Screw Length (L)	Thickness (T)
ERIC1660	50	60.3 mm	150 mm	12	40mm	6 mm
ERIC1676	65	76.1 mm	167 mm	12	40mm	6 mm
ERIC1689	80	88.9 mm	180 mm	12	40mm	6 mm

Table 2/2	
Catalog Number	Static Load
ERIC16114	4000N
ERIC16165	4000N
ERIC16220	6000N
ERIC16273	7500N
ERIC16324	10000N
ERIC1660	4000N
ERIC1676	4000N
ERIC1689	4000N

DIAGRAMS

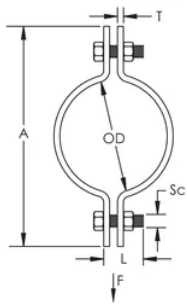

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

