

NUT 2-Screw Clamp for Copper Pipe



FEATURES

Suspends copper pipe services

Cup head fastener

Double bolted

SPECIFICATIONS

Color: Brown

Finish: Polyester

Table 1/2


Catalog Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Width (W)	Thickness (T)
NUT100CUPPC	100	101.6 mm	M10	133 mm	20 mm	3 mm
NUT125CUPPC	125	127 mm	M10	158 mm	25 mm	3 mm
NUT150CUPPC	150	152.4 mm	M10	187 mm	25 mm	3 mm
NUT15CUPPC	15	12.7 mm	M10	44 mm	20 mm	3 mm
NUT20CUPPC	20	19 mm	M10	50 mm	20 mm	3 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Width (W)	Thickness (T)
NUT25CUPPC	25	25.4 mm	M10	56 mm	20 mm	3 mm
NUT32CUPPC	32	31.8 mm	M10	63 mm	20 mm	3 mm
NUT40CUPPC	40	38.1 mm	M10	69 mm	20 mm	3 mm
NUT50CUPPC	50	51.2 mm	M10	82 mm	20 mm	3 mm
NUT65CUPPC	65	63.5 mm	M10	95 mm	20 mm	3 mm
NUT80CUPPC	80	76.2 mm	M10	107 mm	20 mm	3 mm

Table 2/2

Catalog Number	Static Load
NUT100CUPPC	1500N
NUT125CUPPC	2500N
NUT150CUPPC	2500N
NUT15CUPPC	1500N
NUT20CUPPC	1500N
NUT25CUPPC	1500N
NUT32CUPPC	1500N
NUT40CUPPC	1500N
NUT50CUPPC	1500N
NUT65CUPPC	1500N
NUT80CUPPC	1500N

DIAGRAMS

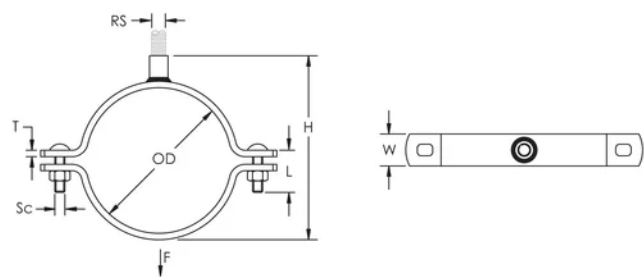

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

