

nVent CADDY Macrofix 250 M8/M10



CERTIFICATIONS



FEATURES

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Color:	Black
Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
MXD058	595870	54 - 58 mm		M8, M10	20 mm	2 mm

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
MXD141	595950	135 - 141 mm		M8, M10	23 mm	2.5 mm
MXD168	595970	165 - 168 mm	150	M8, M10	23 mm	2.5 mm
MXD202	595971	198 - 202 mm		M8, M10	25 mm	3 mm
MXD220	595973	216 - 220 mm	200	M8, M10	25 mm	3 mm
MXD227	595990	220 - 227 mm		M8, M10	30 mm	3 mm
MXD254	595991	249 - 254 mm		M8, M10	30 mm	3 mm
MXD280	595992	274 - 280 mm		M8, M10	30 mm	3 mm
MXD319	595993	313 - 319 mm		M8, M10	30 mm	3 mm

Table 2/2


Catalog Number	Article Number	Screw Diameter metric (Sc)	Screw Length (L)	Static Load	Certifications
MXD058	595870	M6	25mm	1000N	
MXD141	595950	M8	25mm	1500N	
MXD168	595970	M8	25mm	2200N	ITB
MXD202	595971	M8	30mm	2500N	ITB
MXD220	595973	M8	30mm	2500N	ITB
MXD227	595990	M8	30mm	2700N	ITB
MXD254	595991	M8	30mm	2700N	ITB
MXD280	595992	M8	30mm	2700N	ITB

Catalog Number	Article Number	Screw Diameter metric (Sc)	Screw Length (L)	Static Load	Certifications
MXD319	595993	M8	30mm	2700N	ITB

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

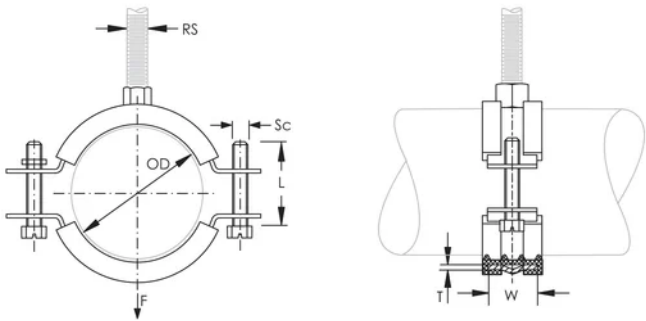

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

