

nVent CADDY Slick Nut



FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	Article Number	Hole Size (HS)	Hole Type	Height (H)	Torque (TQ)	Static Load 1 (F1)
SLICKM8	174340	8 mm	Threaded	17 mm	8 N·m	2700N
SLICKM10	174350	10 mm	Threaded	17 mm	14 N·m Min	2700N
SLICKM12	174550	12 mm	Threaded	17 mm	14 N·m Min	2700N

Table 2/2

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)
SLICKM8	174340	450N	1100N
SLICKM10	174350	450N	1100N


Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)
SLICKM12	174550	450N	1100N

ADDITIONAL PRODUCT DETAILS

Indicated loads are independent of the threaded stud or rod.

Indicated loads are applicable on 14 GA and 12 GA (2 mm and 2.5 mm) strut channels only.

DIAGRAMS

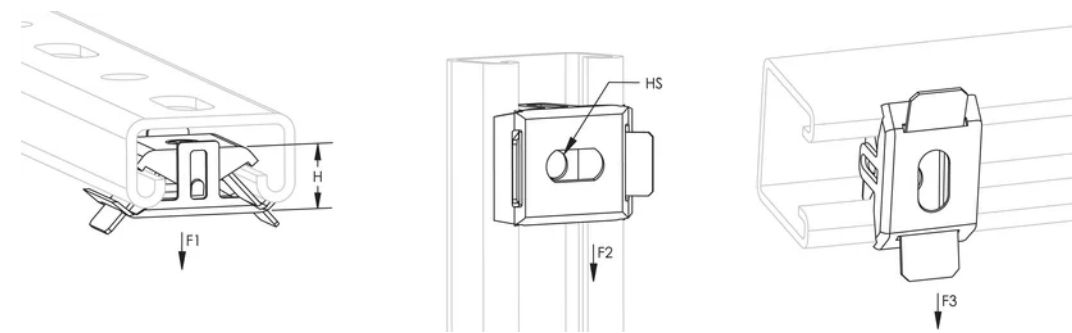

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

