

# nVent CADDY Superfix 243 M8/M10



## CERTIFICATIONS



## FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

**Temperature:** -50 to 110 °C

**Color:** Black

**Finish:** Electrogalvanized

**Material:** Steel;EPDM-SBR Rubber

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
SXD019	400064	15 - 19 mm	10	M8, M10	20 mm	1.2 mm

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
SXD043	400068	40 - 43 mm	32	M8, M10	20 mm	1.2 mm
SXD061	400071	60 - 64 mm	50	M8, M10	20 mm	1.2 mm
SXD058	589350	50 - 55 mm		M8, M10	20 mm	1.2 mm
SXD052	400070	48 - 53 mm	40	M8, M10	20 mm	1.2 mm
SXD023	400065	20 - 23 mm	15	M8, M10	20 mm	1.2 mm
SXD035	400067	31 - 36 mm	25	M8, M10	20 mm	1.2 mm
SXD014	400063	12 - 16 mm	8	M8, M10	20 mm	1.2 mm
SXD028	400066	26 - 30 mm	20	M8, M10	20 mm	1.2 mm
SXD039	589349	36 - 39 mm		M8, M10	20 mm	1.5 mm
SXD080	400074	74 - 80 mm	65	M8, M10	20 mm	2 mm
SXD091	400075	87 - 92 mm	80	M8, M10	20 mm	2 mm
SXD114	400077	108 - 114 mm	100	M8, M10	23 mm	2 mm
SXD073	400073	70 - 73 mm		M8, M10	20 mm	2 mm

Table 2/2


Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load	Certifications
SXD019	400064	5	25mm	1000N	ITB
SXD043	400068	5	25mm	1000N	ITB
SXD061	400071	5	30mm	1300N	ITB

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load	Certifications
SXD058	589350	5	30mm	1300N	ITB
SXD052	400070	5	25mm	1300N	ITB
SXD023	400065	5	25mm	1000N	ITB
SXD035	400067	5	25mm	1000N	ITB
SXD014	400063	5	25mm	1000N	ITB
SXD028	400066	5	25mm	1000N	ITB
SXD039	589349	6	30mm	1000N	
SXD080	400074	6	35mm	1300N	ITB
SXD091	400075	6	35mm	1300N	ITB
SXD114	400077	6	35mm	2200N	ITB
SXD073	400073	6	35mm	1300N	ITB

## ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

## DIAGRAMS

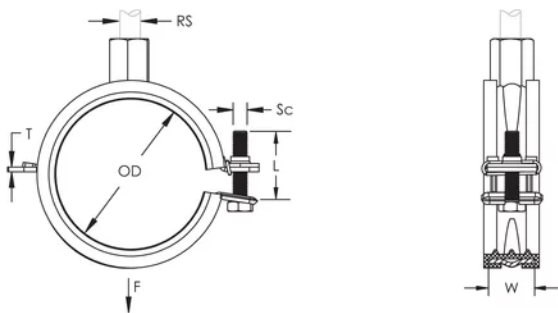

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

