

USC Universal Strut Clamp for PVC



FEATURES

Consists of two clamps, nut and bolt

Fits into open side of strut channel

SPECIFICATIONS

Finish: Polyester


Material: Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC046WH	43 - 45 mm	40	32 mm	2 mm	2670N
USC054WH	54 - 55 mm	50	32 mm	2.5 mm	3780N
USC068WH	66 - 69 mm	65	32 mm	2.5 mm	3780N
USC080WH	77.2 - 82.6 mm	80	32 mm	2.5 mm	3780N
USC093WH	90.0 - 95.3 mm	90	32 mm	2.5 mm	3780N
USC107WH	104.1 - 110 mm	100	32 mm	2.5 mm	3780N

Catalog Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC159WH	155.6 - 162 mm	150	32 mm	3 mm	4000N
USC254WH	250.0 - 257.2 mm	225	32 mm	3 mm	4000N
USC311WH	305.5 - 317 mm	300	32 mm	3 mm	4000N
USC400WH	400 mm	375	32 mm	3 mm	4000N

DIAGRAMS

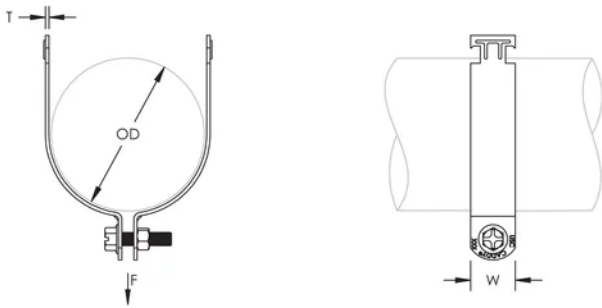

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

