


WBT Performance Cable Tray Bar Splice

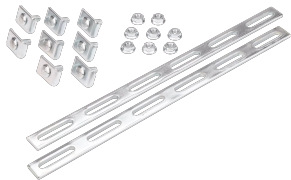

The nVent CADDY WBT Performance Cable Tray Bar Splice offers a versatile solution for straight sections and fittings within shaped wire basket tray systems. Engineered for structural continuity, the Bar Splice delivers enhanced support between tray runs. With a slotted design, contractors can create innovative field configurations—ideal for forming reducers or achieving precise angles. Whether you're adapting tray geometry or reinforcing connections, the Bar Splice ensures a clean, secure fit with finishes that match your installation.

CERTIFICATIONS



FEATURES

Multiple color options to coordinate with cable tray selection

Creates additional support for cable tray runs

Optimal for angles 30 degrees and smaller

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Color	Height	Width	Length	Slot Size	Unit Weight
WBTBSPLICEWH	White	4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg
WBTBSPLICEB	Black	4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg

CatalogNumber	Color	Height	Width	Length	Slot Size	Unit Weight
WBTBSPLICEKIT		4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg
WBTBSPLICEKITBA	Black	4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg
WBTBSPLICEKITWH	White	4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg
WBTBSPLICE		4.55 mm	17.46 mm	304.8mm	6.3 x 36.5 mm	0.127 kg

Table 2/2

Catalog Number	Certifications
WBTBSPLICEWH	
WBTBSPLICEBA	
WBTBSPLICEKIT	UL
WBTBSPLICEKITBA	UL
WBTBSPLICEKITWH	
WBTBSPLICE	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

