

Ground Rod Hex Driving Stud for Externally Threaded Ground Rods



CERTIFICATIONS



FEATURES

Used in conjunction with threaded couplers while driving threaded ground rods

SPECIFICATIONS


Material: Steel

Table 1/1

Catalog Number	Ground Rod Diameter, Nominal	Thread Size (TS)	Length (L)	Certifications
DS12S	1/2"	9/16" UNC	44.5mm	
DS12	1/2"	1/2" UNC	38.1mm	
DS58	5/8"	5/8" UNC	44.5mm	RUS

Catalog Number	Ground Rod Diameter, Nominal	Thread Size (TS)	Length (L)	Certifications
DS58C	5/8"	5/8" UNC	36.6mm	
DS34	3/4"	3/4" UNC	50.8mm	RUS
DS1	1"	1" UNC	63.5mm	

DIAGRAMS

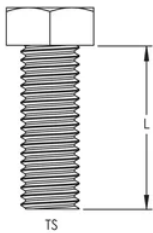

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE