

Inspection Housing, High Density Polyethylene (HDPE)



FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

SPECIFICATIONS

Load Rating: 0.15


Color: Green

Material: High Density Polyethylene (HDPE)

Table 1/1

Catalog Number	Diameter, Grade Level (DG)	Outer Diameter (OD)	Height (H)	Unit Weight
T416BH	260mm	333 mm	254 mm	2 kg
T416B	260mm	333 mm	254 mm	2 kg

DIAGRAMS

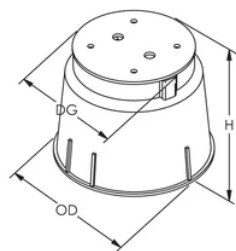

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE