


# Mounting Profiles 19-Inch Partial Height, CIPP

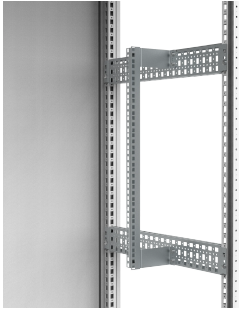

These partial profiles, that can be adjustable in height and depth , allow for the installation of 19" equipment, while customers maintain access to the components installed on the mounting plate within the enclosure.

## FEATURES

Description: Partial height 19" vertical profiles to achieve 482.6 mm (19") mounting requirements on all sides. Adjustable in depth in steps of 25 mm using the CLPK click-in profiles.

Material: 2 mm zinc plated steel.

Pack quantity: 2 pieces with mounting accessories.

Mounting requirements: To be used with brackets CIC in 800 mm wide enclosures.

SPECIFICATIONS

**Thickness:** 2mm  
**Material:** Mild Steel  
**Finish:** Zinc Plated

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Rack Units	Enclosure Material
CIPP06	CIPP06	267mm	45mm	29mm	6U	Mild Steel
CIPP09	CIPP09	400mm	45mm	29mm	9U	Mild Steel
CIPP10	CIPP10	445mm	45mm	29mm	10U	Mild Steel
CIPP11	CIPP11	489mm	45mm	29mm	11U	Mild Steel
CIPP15	CIPP15	667mm	45mm	29mm	15U	Mild Steel
CIPP13	CIPP13	578mm	45mm	29mm	13U	Mild Steel
CIPP18	CIPP18	800mm	45mm	29mm	18U	Mild Steel

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE