


# Small ABS Terminal Box, DABP

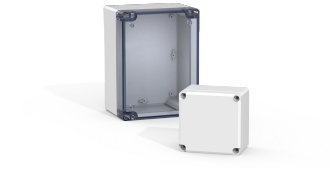

The ABS terminal box range, DABP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The DABP range is well suited for demanding environments, since water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that unnecessary downtime.

## INDUSTRY STANDARDS

CE  
UKCA  
GOST  
IP

## FEATURES

Description: ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material: Body: ABS. Plain cover: ABS. Transparent cover: polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +60 °C.

Flammability: UL94 HB.

Protection: IP 66, 67 | IK 06 (-25 °C), IK 07 (+35 °C).

Finish: RAL 7035.

Delivery: Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide.

Low UV radiation resistance

Polyurethane gasket integrated in the box cover

Temperature resistance: -40 °C to +60 °C

Flammability: UL94 HB

Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide

## SPECIFICATIONS

**Material:** ABS  
**Color:** Light Gray  
**Finish:** Smooth

Table 1/1


Catalog Number	Height (H)	Width (W)	Depth (D)	Max Mounting Depth	Weight	Quick Ship
DABP080809GE	80mm	82mm	56mm	72mm	0.1kg	No
DABP080806GE	80mm	82mm	86mm	42mm	0.1kg	No
DABP081206GE	80mm	120mm	56mm	42mm	0.15kg	No
DABP081209GE	80mm	120mm	86mm	72mm	0.2kg	No
DABP081606GE	80mm	160mm	56mm	42mm	0.2kg	No
DABP081609GE	80mm	160mm	86mm	72mm	0.2kg	No
DABP121206GE	120mm	122mm	56mm	42mm	0.2kg	No
DABP121209GE	120mm	122mm	86mm	72mm	0.25kg	No
DABP121609GE	120mm	160mm	91mm	77mm	0.35kg	No
DABP122009GE	120mm	200mm	86mm	72mm	0.35kg	No
DABP152008GE	150mm	200mm	76mm	62mm	0.4kg	No
DABP050504GE	53mm	55mm	36mm	27.5mm	0.5kg	No
DABP162409GE	160mm	240mm	91mm	77mm	0.55kg	No
DABP162412GE	160mm	240mm	121mm	107mm	0.7kg	No
DABP050704GE	53mm	65mm	36mm	25mm	0.8kg	No
DABP233009GE	230mm	300mm	86mm	72mm	0.85kg	No

Catalog Number	Height (H)	Width (W)	Depth (D)	Max Mounting Depth	Weight	Quick Ship
DABP233011GE	230mm	300mm	111mm	97mm	1kg	No

### ADDITIONAL PRODUCT DETAILS

Note: Terminal box, with polycarbonate transparent cover fitted, can be ordered by replacing GE with TE in the item number.

### DIAGRAMS

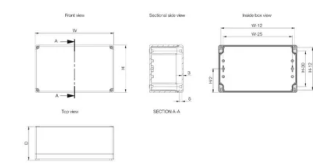

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE