


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

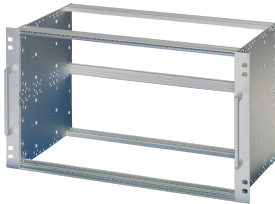

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

CERTIFICATIONS



FEATURES

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

SPECIFICATIONS

Static Load:	15kg
Material:	Aluminum
EMC Shielding:	No
Product Type:	Subrack/Chassis

Table 1/3

Catalog Number	Rack Height	Depth	Package Quantity	For Mounting	Board Depth	Gasket Type
21500-077	3U	235mm	1	Backplane	220mm	Textile EMC
21500-078	6U	235mm	1	Backplane	220mm	Textile EMC

Table 2/3

Catalog Number	Shock and Vibration Tolerance	Handle Included	Mounting	Complies With	Finish	Rack Width
21500-077	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP
21500-078	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP

Table 3/3

Catalog Number	Quick Ship
21500-077	No
21500-078	No

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE