


Mounting Plate for 19" Case and Subrack

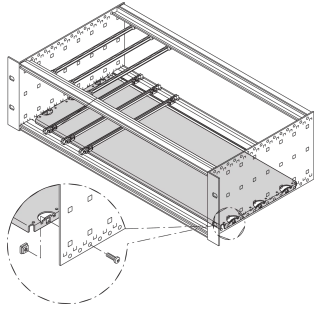

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



FEATURES

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

SPECIFICATIONS

- Material:** Aluminum
- Product Type:** Mounting Plate
- Works With:** Subracks

Table 1/2

Catalog Number	Rack Width	Package Quantity	Depth	Product Family	Width	Certifications
34562-745	28HP	1	112.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS

CatalogNumber	Rack Width	Package Quantity	Depth	Product Family	Width	Certifications
34562-749	28HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-746	42HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-753	28HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-747	63HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-757	28HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-750	42HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	217.99mm	RoHS
34562-748	84HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-754	42HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-751	63HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	324.67mm	RoHS
34562-758	42HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-752	84HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	431.35mm	RoHS
34562-755	63HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-759	63HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS

CatalogNumber	Rack Width	Package Quantity	Depth	Product Family	Width	Certifications
34562-756	84HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-760	84HP	1	292.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-870	84HP	1	352.5mm	EuropacPRO	431.35mm	
34562-871	84HP	1	412.5mm	EuropacPRO	431.35mm	

Table 2/2

Catalog Number	Quick Ship
34562-745	No
34562-749	No
34562-746	No
34562-753	No
34562-747	No
34562-757	No
34562-750	No
34562-748	No
34562-754	No
34562-751	No
34562-758	No
34562-752	No

Catalog Number	Quick Ship
34562-755	No
34562-759	No
34562-756	No
34562-760	No
34562-870	No
34562-871	No

ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE