

J-TI/T Rod to C Purlin Clip



FEATURES

Attaches to joists and C purlin

Supports threaded rod

Threaded rod hanger can swivel to provide a vertical dropdown

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	A	Static Load
J1T10	160220	11 mm	Plain	1.5 - 4 mm	10 mm Min	700N
J1M6TI	174870	6 mm	Threaded	1.5 - 4 mm	10 mm Min	700N
J1M8TI	174960	8 mm	Threaded	1.5 - 4 mm	10 mm Min	700N
J1M10TI	175050	10 mm	Threaded	1.5 - 4 mm	10 mm Min	700N
J2M8TI	174970	8 mm	Threaded	4.0 - 6.5 mm	10 mm Min	700N

CatalogNumber	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	A	Static Load
J2M10TI	175060	10 mm	Threaded	4.0 - 6.5 mm	10 mm Min	700N
J2M6TI	174880	6 mm	Threaded	4.0 - 6.5 mm	10 mm Min	700N

DIAGRAMS

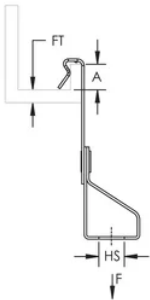

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

