


# Cable Entry Gland Plate Connected Divider, CCFD

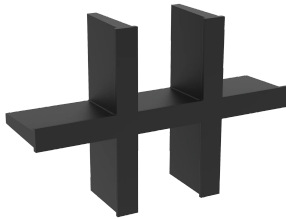

With the click-in CCFD inlays, dimensioning of the frame opening can be adjusted based on the grommet being used.

## INDUSTRY STANDARDS

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

## FEATURES

Description: With the CCFD click-in inlays, dimensioning of the frame opening can be adjusted based on to the grommet being used. An audible click confirms correct installation. This flexible cable entry configuration enables you to accommodate various requirements for cables, lines, tubing, pneumatic and hydraulic lines.

Finish: Black

Flammability: UL94 V-0

Material: Polyamide 6.6 / TPE

Pack quantity: 5pcs

Protection: IP66, NEMA 1, 4x, 12 (Indoor use only)

Temperature resistance: -40°C to +90°C

SPECIFICATIONS

| Table 1/1      |        |       |        |          |           |       |
|----------------|--------|-------|--------|----------|-----------|-------|
| Catalog Number | Height | Width | Depth  | Material | Finish    | Color |
| CCFD1          | 5mm    | 45mm  | 17.7mm | Plastic  | Untreated | Black |
| CCFD2          | 25mm   | 45mm  | 17.7mm | Plastic  | Untreated | Black |
| CCFD4          | 45mm   | 45mm  | 17.7mm | Plastic  | Untreated | Black |
| CCFD6          | 70mm   | 45mm  | 17.7mm | Plastic  | Untreated | Black |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE