


# 19" Pusher Fan, 3 U, Axial

## Power Utilities

Fan tray with integrated pusher fan.

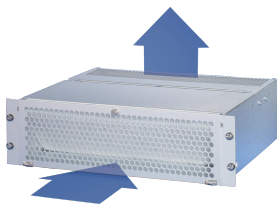

### CERTIFICATIONS



### FEATURES

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

### SPECIFICATIONS

Table 1/1

| Catalog Number | Input Voltage AC |
|----------------|------------------|
| 10713-546      | 230 V min        |
| 10713-547      | 115 V min        |

## ADDITIONAL PRODUCT DETAILS

---

With cover plates, this pusher fan can be re-fitted to different cooling concepts

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**