


# EuropacPRO Cover Plate, Universal

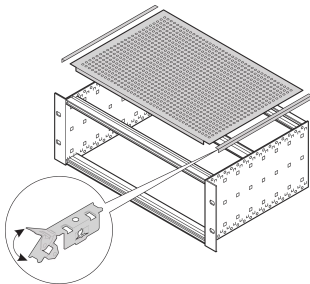

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be used is non-standard boards will be assembled into the subrack.

## CERTIFICATIONS



## FEATURES

Shielding is provided by optional EMC stainless steel gaskets, between cover plate and side panel

For variable positioning of horizontal rails e.g. for PCBs with non-standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Material:</b>       | Aluminum    |
| <b>Product Type:</b>   | Cover Plate |
| <b>Product Family:</b> | EuropacPRO  |
| <b>Finish:</b>         | Passivated  |
| <b>Works With:</b>     | Subracks    |
| <b>Type:</b>           | Universal   |

Table 1/1

| Catalog Number | Rack Width | Depth | Package Quantity | Package Unit | Quick Ship |
|----------------|------------|-------|------------------|--------------|------------|
| 24560-031      | 42HP       | 175mm | 2                | Pair         | No         |

| Catalog Number | Rack Width | Depth | Package Quantity | Package Unit | Quick Ship |
|----------------|------------|-------|------------------|--------------|------------|
| 24560-032      | 42HP       | 235mm | 2                | Pair         | No         |
| 24560-041      | 63HP       | 175mm | 2                | Pair         | No         |
| 24560-033      | 42HP       | 295mm | 2                | Pair         | No         |
| 24560-042      | 63HP       | 235mm | 2                | Pair         | No         |
| 24560-051      | 84HP       | 175mm | 2                | Pair         | No         |
| 24560-043      | 63HP       | 295mm | 2                | Pair         | No         |
| 24560-052      | 84HP       | 235mm | 2                | Pair         | No         |
| 24560-053      | 84HP       | 295mm | 2                | Pair         | No         |
| 24560-054      | 84HP       | 355mm | 2                | Pair         | No         |
| 24560-055      | 84HP       | 415mm | 2                | Pair         | No         |
| 24560-056      | 84HP       | 475mm | 2                | Pair         | No         |

## ADDITIONAL PRODUCT DETAILS

In addition, 4 contact strips per subrack are required to affix cover to horizontal rail.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**