


# EuropacPRO Rugged Rear Angle for Textile EMC Gasket

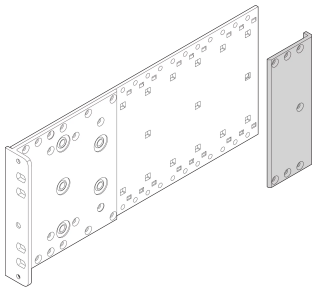

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

## CERTIFICATIONS



## FEATURES

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

## SPECIFICATIONS

|                        |            |
|------------------------|------------|
| <b>Material:</b>       | Aluminum   |
| <b>Product Type:</b>   | Cover      |
| <b>Product Family:</b> | EuropacPRO |
| <b>Type:</b>           | Rugged     |
| <b>Works With:</b>     | Subracks   |

Table 1/2

| Catalog Number | Rack Height | Design Feature | Package Quantity | Height  | Package Unit | Certifications |
|----------------|-------------|----------------|------------------|---------|--------------|----------------|
| 24566-497      | 6U          | CPCI           | 2                | 265.9mm | Pair         |                |

| CatalogNumber | Rack Height | Design Feature | Package Quantity | Height  | Package Unit | Certifications |
|---------------|-------------|----------------|------------------|---------|--------------|----------------|
| 24566-197     | 3U          | CPCI           | 2                | 132.6mm | Pair         |                |
| 24566-199     | 3U          |                | 2                | 132.6mm | Pair         | RoHS           |
| 24566-499     | 6U          |                | 2                | 265.9mm | Pair         | RoHS           |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 24566-497      | No         |
| 24566-197      | No         |
| 24566-199      | No         |
| 24566-499      | No         |

## ADDITIONAL PRODUCT DETAILS

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**