

# 108 Two Hole Strap for CPVC Pipe



## CERTIFICATIONS



## FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screws

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1080150EG	597825	40	48.3 mm	5.8 mm	112.7 mm	87.3 mm
1080075EG	597822	20	26.9 mm	5.8 mm	82.6 mm	57.2 mm
1080200EG	597826	50	60.3 mm	5.8 mm	125.4 mm	100 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1080125EG	597824	32	42.2 mm	5.8 mm	108 mm	82.6 mm
1080100EG	597823	25	33.7 mm	5.8 mm	88.9 mm	63.5 mm

Table 2/2

Catalog Number	Article Number	C	Hanger Spacing
1080150EG	597825	30.2 mm	2.1 m Max
1080075EG	597822	30.2 mm	1.65 m Max
1080200EG	597826	30.2 mm	2.4 m Max
1080125EG	597824	30.2 mm	1.95 m Max
1080100EG	597823	30.2 mm	1.8 m Max

## DIAGRAMS

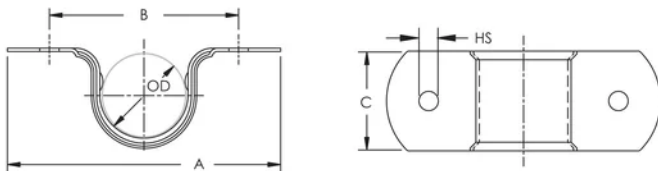

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

