


Horizontal Adjustable Coupler

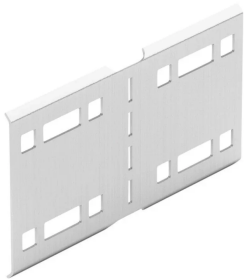

CERTIFICATIONS



FEATURES

Provides high-strength joint with SPEEDWAY Cable Ladder profile

Extended geometry allows greater cable ladder joint adjustments

Installs quickly and easily with included hardware


Multiple slots allow for field adjustments

SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Material	Finish	A	B	C
CLSW4HACGA	842020	Steel	Hot-Dip Galvanized	190 mm	62 mm	2 mm

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

