

TDHM Trapezoidal Deck Hanger with Threaded Nut



CERTIFICATIONS



FEATURES

Easy install

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel


Table 1/1

Catalog Number	Article Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)	D
TDHM10	179950	10	6.8 mm	14 mm	10 1/2mm	50 mm Max
TDHM8	179940	8	6.8 mm	14 mm	10 1/2mm	50 mm Max

CatalogNumber	Article Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)	D
TDHM6	179930	6	6.8 mm	14 mm	10 1/2mm	50 mm Max

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

DIAGRAMS

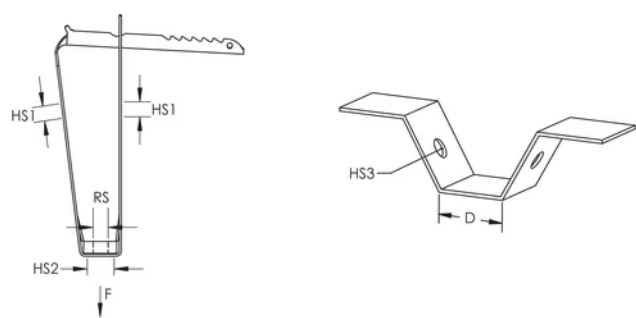

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

