


# Front Handle One-Piece, Width 12.2 mm

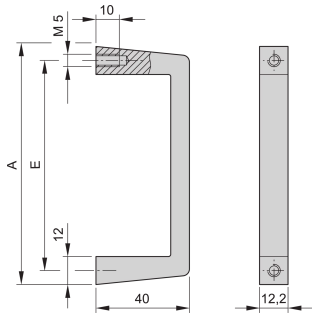

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

## CERTIFICATIONS



## FEATURES

Static load-carrying capacity 30 kg/pair

Bolted from rear

## SPECIFICATIONS

|                        |            |
|------------------------|------------|
| <b>Material:</b>       | Aluminum   |
| <b>Product Family:</b> | EuropacPRO |
| <b>Product Type:</b>   | Handle     |
| <b>Works With:</b>     | Subracks   |

Table 1/2

| Catalog Number | Rack Height | Finish   | Package Quantity | Handle Type | Color  | Torque |
|----------------|-------------|----------|------------------|-------------|--------|--------|
| 10501-116      | 1U          | Anodized | 1                | Straight    | Silver |        |
| 10501-016      | 2U          | Anodized | 1                | Straight    | Silver |        |

| CatalogNumber | Rack Height | Finish   | Package Quantity | Handle Type   | Color  | Torque |
|---------------|-------------|----------|------------------|---------------|--------|--------|
| 10501-004     | 2U          | Anodized | 1                | Straight      | Silver |        |
| 10501-025     | 2U          | Anodized | 1                | Straight      | Black  |        |
| 10501-005     | 3U          | Anodized | 1                | Straight      | Silver | 2.4N·m |
| 10501-020     | 3U          | Anodized | 1                | Angled Handle | Silver | 2.4N·m |
| 10501-026     | 3U          | Anodized | 1                | Straight      | Black  | 2.4N·m |
| 10501-006     | 4U          | Anodized | 1                | Straight      | Silver |        |
| 10501-018     | 4U          | Anodized | 1                | Straight      | Silver | 2.4N·m |
| 10501-021     | 4U          | Anodized | 1                | Angled Handle | Silver | 2.4N·m |
| 10501-027     | 4U          | Anodized | 1                | Straight      | Black  |        |
| 10501-007     | 5U          | Anodized | 1                | Straight      | Silver |        |
| 10501-028     | 5U          | Anodized | 1                | Straight      | Black  |        |
| 10501-022     | 6U          | Anodized | 1                | Angled Handle | Silver | 2.4N·m |
| 10501-008     | 6U          | Anodized | 1                | Straight      | Silver | 2.4N·m |
| 10501-029     | 6U          | Anodized | 1                | Straight      | Black  | 2.4N·m |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 10501-116      | No         |
| 10501-016      | No         |
| 10501-004      | No         |

| Catalog Number | Quick Ship |
|----------------|------------|
| 10501-025      | No         |
| 10501-005      | No         |
| 10501-020      | No         |
| 10501-026      | No         |
| 10501-006      | No         |
| 10501-018      | No         |
| 10501-021      | No         |
| 10501-027      | No         |
| 10501-007      | No         |
| 10501-028      | No         |
| 10501-022      | No         |
| 10501-008      | No         |
| 10501-029      | No         |

## ADDITIONAL PRODUCT DETAILS

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**