


# Air Terminal Base, Pipe Mount, Imperial Thread



## CERTIFICATIONS

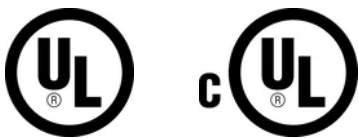

## FEATURES

Mounts air terminal to horizontal pipe or vertical pipe using Right Angle Extension Adaptor

Provided with cable clamp to support cable next to pipe

## SPECIFICATIONS


Table 1/2

| Catalog Number | Material | Finish | Thread Size (TS) | Outer Diameter (OD) | Depth (D) | Width (W) |
|----------------|----------|--------|------------------|---------------------|-----------|-----------|
| LPA37112       | Aluminum |        | 1/2" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPA37158       | Aluminum |        | 5/8" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPC37112       | Copper   |        | 1/2" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPC37138       | Copper   |        | 3/8" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |

| CatalogNumber | Material | Finish | Thread Size (TS) | Outer Diameter (OD) | Depth (D) | Width (W) |
|---------------|----------|--------|------------------|---------------------|-----------|-----------|
| LPC37158      | Copper   |        | 5/8" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPC371L12     | Copper   | Tinned | 1/2" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPC371L38     | Copper   | Tinned | 3/8" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |
| LPC371L58     | Copper   | Tinned | 5/8" UNC         | 25.4 - 63.5 mm      | 38.86mm   | 92.2 mm   |

| Table 2/2      |             |
|----------------|-------------|
| Catalog Number | Unit Weight |
| LPA37112       | 0.29 kg     |
| LPA37158       | 0.29 kg     |
| LPC37112       | 0.65 kg     |
| LPC37138       | 0.65 kg     |
| LPC37158       | 0.65 kg     |
| LPC371L12      | 0.65 kg     |
| LPC371L38      | 0.65 kg     |
| LPC371L58      | 0.65 kg     |

DIAGRAMS

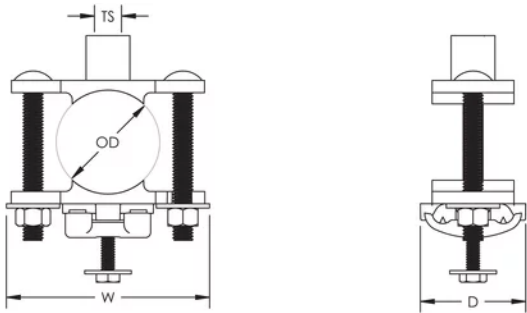

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE