


# 2000 Beam Clamp Kit

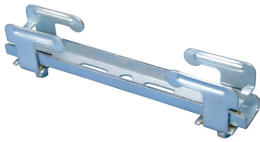

## FEATURES

Light duty system

Includes clamp and U channel

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Length (L)	A	B	C	D
2300EG	570160	300mm	25 mm	25 mm	65 mm	25 mm
2200EG	570140	200mm	25 mm	25 mm	65 mm	25 mm
2400EG	570180	400mm	25 mm	25 mm	65 mm	25 mm

Table 2/2

Catalog Number	Article Number	E	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
2300EG	570160	30.5 mm	1700N	490N	340N
2200EG	570140	30.5 mm	1700N	490N	340N


Catalog Number	Article Number	E	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
2400EG	570180	30.5 mm	1700N	490N	340N

**Thickness (T):** 2 mm  
**Screw Diameter (Sc):** 6  
**Hole Size (HS):** 11 mm  
**Height (H):** 12 mm  
**Width (W):** 25 mm  
**Torque (TQ):** 30 N·m  
**Flange Thickness (FT):** 11 mm Max

## ADDITIONAL PRODUCT DETAILS

For a secure grip the channel must extend to the outer edge of each beam clamp.

## DIAGRAMS

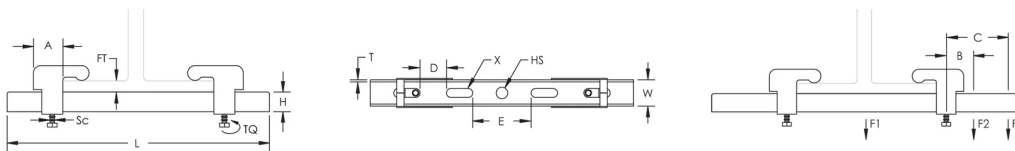

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical  
 Support

### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

