

nVent CADDY Speed Link SLDM with Hook



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Ideal for supporting lighting, ductwork and other installation projects

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFICATIONS

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel

Table 1/1

Catalog Number	Article Number	Wire Rope Length	A	B	C	Static Load
SLDM615L2	196029	2m	58.4 mm	22.9 mm	6.4 mm	195N

CatalogNumber	Article Number	Wire Rope Length	A	B	C	Static Load
SLDM615L1	196028	1m	58.4 mm	22.9 mm	6.4 mm	195N


Rod Size (RS): 6

Length (L): 7mm

Width (W): 9.2 mm

Height (H): 24.5 mm

DIAGRAMS

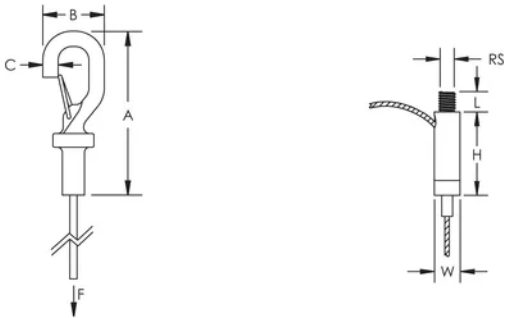

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

