


STRC CU Strap Clamp for Copper Tube

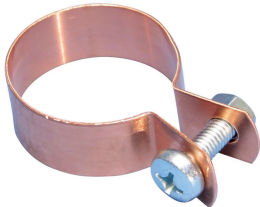

FEATURES

Includes fasteners, screw and nut


SPECIFICATIONS

Material: Copper

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
STRC028CU	574210	28 mm	15 mm	0.6 mm	6	16mm
STRC022CU	574200	22 mm	15 mm	0.6 mm	6	16mm
STRC018CU	574190	18 mm	15 mm	0.6 mm	6	16mm
STRC015CU	574180	15 mm	15 mm	0.6 mm	6	16mm
STRC012CU	574170	12 mm	15 mm	0.6 mm	6	16mm

DIAGRAMS

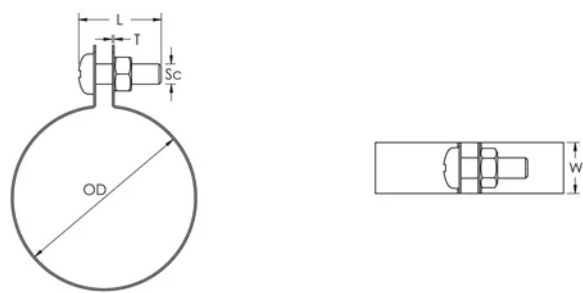

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

