

# CPPS Tapered Plastic Screw-In Plug with Steel Cap for A12



## FEATURES

Designed for use with the A12 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Steel cap provides added protection from damage

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Material:** High Density Polyethylene (HDPE);Steel

Table 1/2

Catalog Number	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL10CPPS	153600	10 mm	#3		17 mm	15 mm
EL12CPPS	153610	12 mm	#4	10M	17 mm	15 mm
EL14CPPS	153620	14 mm			22 mm	15 mm
EL16CPPS	153630	16 mm	#5	15M	22 mm	15 mm


CatalogNumber	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL18CPPS	153640	18 mm			27 mm	15 mm
EL20CPPS	153650	20 mm	#6	20M	27 mm	15 mm
EL22CPPS	153660	22 mm	#7		33 mm	18 mm
EL25CPPS	153670	25 mm	#8	25M	33 mm	18 mm
EL28CPPS	153680	28 mm	#9	30M	37 mm	18 mm
EL30CPPS	153690	30 mm			37 mm	18 mm
EL32CPPS	153700	32 mm	#10		42 mm	18 mm
EL40CPPS	153710	40 mm			52 mm	18 mm
EL50TCPPS	154970	50 mm			64 mm	18 mm

Table 2/2

Catalog Number	Article Number	Color
EL10CPPS	153600	Yellow
EL12CPPS	153610	Red
EL14CPPS	153620	Green
EL16CPPS	153630	Black
EL18CPPS	153640	White
EL20CPPS	153650	Yellow
EL22CPPS	153660	Blue
EL25CPPS	153670	Red

Catalog Number	Article Number	Color
EL28CPPS	153680	Black
EL30CPPS	153690	White
EL32CPPS	153700	Yellow
EL40CPPS	153710	Green
EL50TCPPS	154970	Black

## DIAGRAMS

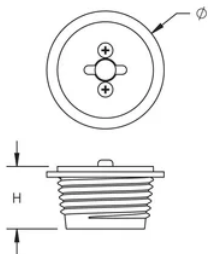

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**