

# 2HPS Two Hole Pipe Strap



## FEATURES

Light duty support of pipe

Attaches directly to the face of a horizontal or vertical structural member

## SPECIFICATIONS

**Finish:** Pregalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Width (W)	Thickness (T)
008017EG	400678	10	17.2 mm	7 mm	20 mm	1 mm
008021EG	400679	15	21.3 mm	7 mm	20 mm	1 mm
008027EG	400680	20	26.9 mm	7 mm	20 mm	1 mm
008034EG	400681	25	33.7 mm	7 mm	20 mm	1 mm
008042EG	400682	32	42.4 mm	7 mm	20 mm	1 mm
008048EG	400683	40	48.3 mm	7 mm	20 mm	1 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Width (W)	Thickness (T)
008060EG	400684	50	60.3 mm	7 mm	20 mm	1 mm

### DIAGRAMS

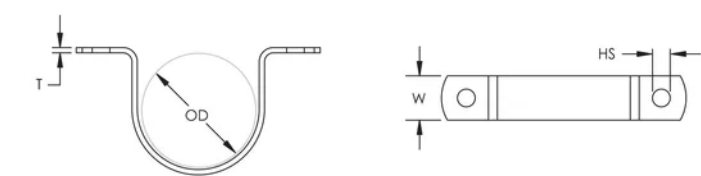

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

