

# 4G16 Twist Clip with Stud



## CERTIFICATIONS



## FEATURES

Supports electrical fixtures from acoustical T-grid

No tools required for installation

Fast, easy and secure twist-on installation

Nut sold separately

## SPECIFICATIONS

**Material:** Spring Steel;Steel


Table 1/2

Catalog Number	Article Number	Finish	Color	Flange Thickness (FT)	T-Grid Size	Screw Diameter (Sc)
4G16M11	178600	nVent CADDY Armour	Gray	1.5 mm	24mm	6
4G16M11WH	178620	Painted	White	1.5 mm	24mm	6

CatalogNumber	Article Number	Finish	Color	Flange Thickness (FT)	T-Grid Size	ScrewDiameter (Sc)
4G16M16	171900	nVent CADDY Armour	Gray	1.5 mm	24mm	6
4G16M16WH	576940	Painted	White	1.5 mm	24mm	6
4G16M25	176880	nVent CADDY Armour	Gray	1.5 mm	24mm	6
4G16M7	178590	nVent CADDY Armour	Gray	1.5 mm	24mm	6

Table 2/2			
Catalog Number	Article Number	Screw Length (L)	Static Load
4G16M11	178600	11mm	220N
4G16M11WH	178620	11mm	220N
4G16M16	171900	16mm	220N
4G16M16WH	576940	16mm	220N
4G16M25	176880	25mm	220N
4G16M7	178590	7mm	220N

### DIAGRAMS

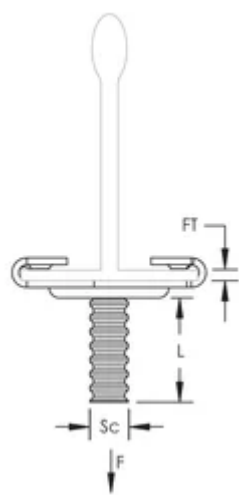

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

