

# CHK Chain



## CERTIFICATIONS



## FEATURES

Versatile non-welded double loop chain

Conforms to DIN 5686

## SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	Length (L)	A	B	D	Static Load
CHK22K	385860	30m	28 mm	9 mm	2 mm	400N
CHK25K	385870	30m	31 mm	10 mm	2.2 mm	500N
CHK27K	385880	30m	35 mm	11 mm	2.5 mm	700N

CatalogNumber	Article Number	Length (L)	A	B	D	Static Load
CHK30K	385890	30m	39 mm	12.5 mm	2.8 mm	900N
CHK32K	385900	25m	41 mm	14 mm	3.1 mm	1200N

### DIAGRAMS

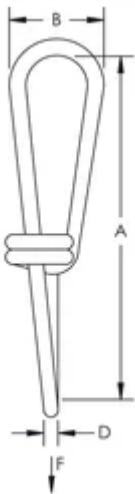

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

