


PEMSA Wire Basket Tray Rapide

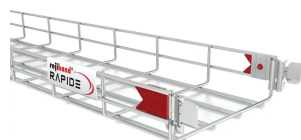

The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICATIONS



FEATURES

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFICATIONS

Material: Carbon Steel

Finish: Electrogalvanized

Table 1/2

| Catalog Number | Article Number | Length (L) | Height (H) | Width (W) | A | Unit Weight |
|-------------------|----------------|------------|------------|-----------|-------|-------------|
| WBT100X100Q BG | 823015 | 3000mm | 100 mm | 100 mm | 32 mm | 3.27 kg |

| CatalogNumber | Article Number | Length (L) | Height (H) | Width (W) | A | Unit Weight |
|-------------------|----------------|------------|------------|-----------|-------|-------------|
| WBT100X100Q EG | 823014 | 3000mm | 100 mm | 100 mm | 32 mm | 3.27 kg |
| WBT100X150Q BG | 823025 | 3000mm | 100 mm | 150 mm | 32 mm | 3.45 kg |
| WBT100X150Q EG | 823024 | 3000mm | 100 mm | 150 mm | 32 mm | 3.45 kg |
| WBT100X200Q BG | 823035 | 3000mm | 100 mm | 200 mm | 32 mm | 4.14 kg |
| WBT100X200Q EG | 823034 | 3000mm | 100 mm | 200 mm | 32 mm | 4.14 kg |
| WBT100X300Q BG | 823045 | 3000mm | 100 mm | 300 mm | 32 mm | 6.15 kg |
| WBT100X300Q EG | 823044 | 3000mm | 100 mm | 300 mm | 32 mm | 6.15 kg |
| WBT100X400Q BG | 823055 | 3000mm | 100 mm | 400 mm | 32 mm | 7.23 kg |
| WBT100X400Q EG | 823054 | 3000mm | 100 mm | 400 mm | 32 mm | 7.23 kg |
| WBT100X450Q BG | 823085 | 3000mm | 100 mm | 450 mm | 32 mm | 7.44 kg |
| WBT100X450Q EG | 823084 | 3000mm | 100 mm | 450 mm | 32 mm | 7.44 kg |
| WBT100X500Q BG | 823065 | 3000mm | 100 mm | 500 mm | 32 mm | 8.34 kg |
| WBT100X500Q EG | 823064 | 3000mm | 100 mm | 500 mm | 32 mm | 8.34 kg |

| CatalogNumber | Article Number | Length (L) | Height (H) | Width (W) | A | Unit Weight |
|-------------------|----------------|------------|------------|-----------|-------|-------------|
| WBT100X600Q BG | 823075 | 3000mm | 100 mm | 600 mm | 32 mm | 9.42 kg |
| WBT100X600Q EG | 823074 | 3000mm | 100 mm | 600 mm | 32 mm | 9.42 kg |
| WBT60X100QB G | 820015 | 3000mm | 60 mm | 100 mm | 32 mm | 2.43 kg |
| WBT60X100QE G | 820014 | 3000mm | 60 mm | 100 mm | 32 mm | 2.43 kg |
| WBT60X150QB G | 820025 | 3000mm | 60 mm | 150 mm | 32 mm | 2.6 kg |
| WBT60X150QE G | 820024 | 3000mm | 60 mm | 150 mm | 32 mm | 2.6 kg |
| WBT60X200QB G | 820035 | 3000mm | 60 mm | 200 mm | 32 mm | 3.33 kg |
| WBT60X200QE G | 820034 | 3000mm | 60 mm | 200 mm | 32 mm | 3.33 kg |
| WBT60X300QB G | 820045 | 3000mm | 60 mm | 300 mm | 32 mm | 5.13 kg |
| WBT60X300QE G | 820044 | 3000mm | 60 mm | 300 mm | 32 mm | 5.13 kg |
| WBT60X400QB G | 820055 | 3000mm | 60 mm | 400 mm | 32 mm | 6.21 kg |
| WBT60X400QE G | 820054 | 3000mm | 60 mm | 400 mm | 32 mm | 6.21 kg |
| WBT60X450QB G | 820085 | 3000mm | 60 mm | 450 mm | 32 mm | 6.39 kg |

| CatalogNumber | Article Number | Length (L) | Height (H) | Width (W) | A | Unit Weight |
|---------------|----------------|------------|------------|-----------|-------|-------------|
| WBT60X450QEG | 820084 | 3000mm | 60 mm | 450 mm | 32 mm | 6.39 kg |
| WBT60X500QBG | 820065 | 3000mm | 60 mm | 500 mm | 32 mm | 7.35 kg |
| WBT60X500QEG | 820064 | 3000mm | 60 mm | 500 mm | 32 mm | 7.35 kg |
| WBT60X600QBG | 820079 | 3000mm | 60 mm | 600 mm | 32 mm | 8.43 kg |
| WBT60X600QEG | 820078 | 3000mm | 60 mm | 600 mm | 32 mm | 8.43 kg |
| WBT60X60QBG | 820005 | 3000mm | 60 mm | 60 mm | 32 mm | 2.32 kg |


Table 2/2

| Catalog Number | Article Number | Color |
|----------------|----------------|-------|
| WBT100X100QBG | 823015 | Black |
| WBT100X100QEG | 823014 | Gray |
| WBT100X150QBG | 823025 | Black |
| WBT100X150QEG | 823024 | Gray |
| WBT100X200QBG | 823035 | Black |
| WBT100X200QEG | 823034 | Gray |
| WBT100X300QBG | 823045 | Black |
| WBT100X300QEG | 823044 | Gray |
| WBT100X400QBG | 823055 | Black |

| Catalog Number | Article Number | Color |
|----------------|----------------|-------|
| WBT100X400QEG | 823054 | Gray |
| WBT100X450QBG | 823085 | Black |
| WBT100X450QEG | 823084 | Gray |
| WBT100X500QBG | 823065 | Black |
| WBT100X500QEG | 823064 | Gray |
| WBT100X600QBG | 823075 | Black |
| WBT100X600QEG | 823074 | Gray |
| WBT60X100QBG | 820015 | Black |
| WBT60X100QEG | 820014 | Gray |
| WBT60X150QBG | 820025 | Black |
| WBT60X150QEG | 820024 | Gray |
| WBT60X200QBG | 820035 | Black |
| WBT60X200QEG | 820034 | Gray |
| WBT60X300QBG | 820045 | Black |
| WBT60X300QEG | 820044 | Gray |
| WBT60X400QBG | 820055 | Black |
| WBT60X400QEG | 820054 | Gray |
| WBT60X450QBG | 820085 | Black |

| Catalog Number | Article Number | Color |
|----------------|----------------|-------|
| WBT60X450QEG | 820084 | Gray |
| WBT60X500QBG | 820065 | Black |
| WBT60X500QEG | 820064 | Gray |
| WBT60X600QBG | 820079 | Black |
| WBT60X600QEG | 820078 | Gray |
| WBT60X60QBG | 820005 | Black |

DIAGRAMS

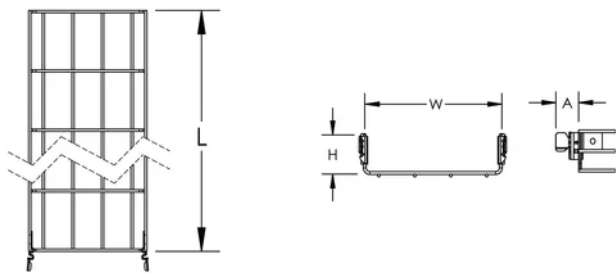

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

