

605 Two-Rod Roller Hanger



FEATURES

Suspends pipe from two rods where longitudinal movement in pipe may occur due to expansion or contraction

Conforms with Federal Specification WW-H-171 (Type 42), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 41)

SPECIFICATIONS

Material: Steel;Cast Iron

Finish: Hot-Dip Galvanized;Electrogalvanized

Table 1/1


Catalog Number	Rod Size (RS)	A	B	Static Load
6050600HD	M20	101.6 mm	250.8 mm	4700N
6051200HD	M22	190.5 mm	419.1 mm	10600N
6051000HD	M22	161.93 mm	355.6 mm	7600N
6050800HD	M22	130.18 mm	304.8 mm	6000N
6052000HD	M32	295.28 mm	622.3 mm	20200N
6052400HD	M38	355.6 mm	731.8 mm	27400N

ADDITIONAL PRODUCT DETAILS

Roll and sockets are hot-dip galvanized cast iron and axle is electrogalvanized carbon steel.

Install in accordance with applicable code.

DIAGRAMS

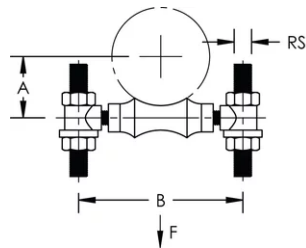

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

