

DUPLO NI Double Pipe Clamp



FEATURES

Fast installation of parallel pipes from a single anchor

Height adjustable

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	A
DUPLON22EG	596041	22 mm	15	20 mm	1.5 mm	60 mm
DUPLON28EG	596042	28 mm	20	20 mm	1.5 mm	60 mm
DUPLON15EG	596040	15 mm		20 mm	1.5 mm	60 mm

Table 2/2

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)
DUPLON22EG	596041	6	16mm
DUPLON28EG	596042	6	16mm

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)
DUPLON15EG	596040	6	16mm

DIAGRAMS

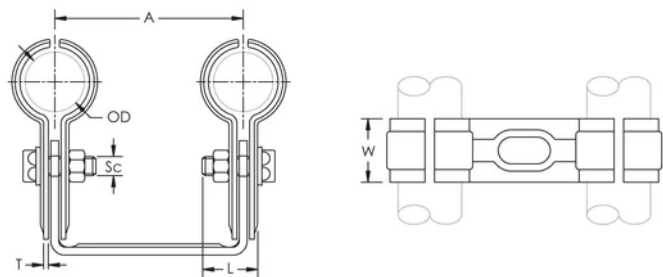

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

