

H-MSM Conduit/Pipe to Flange Clip, Side Mount



CERTIFICATIONS



FEATURES

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
12M24SMS1	179690	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	3 - 8 mm	90N
16M24SM	173720	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	3 - 8 mm	120N
20M24SM	171720	Spring Steel	nVent CADDY Armour	35 - 42 mm	3 - 8 mm	120N
24M24SM	176690	Spring Steel	nVent CADDY Armour	42 - 50 mm	3 - 8 mm	120N

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
32M24SM	173830	Spring Steel	nVent CADDY Armour	50 - 60 mm	3 - 8 mm	120N
6M24SM	173640	Spring Steel	nVent CADDY Armour	14 - 18 mm	3 - 8 mm	120N
812M24SM	160050	Spring Steel	nVent CADDY Armour	18 - 30 mm	3 - 8 mm	120N
8M24SMS1	179650	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	3 - 8 mm	90N
12M58SMS1	179700	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	8 - 14 mm	90N
16M58SM	173730	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	8 - 14 mm	120N
20M58SM	173770	Spring Steel	nVent CADDY Armour	35 - 42 mm	8 - 14 mm	120N
24M58SM	173800	Spring Steel	nVent CADDY Armour	42 - 50 mm	8 - 14 mm	120N
32M58SM	173840	Spring Steel	nVent CADDY Armour	50 - 60 mm	8 - 14 mm	120N
6M58SM	171980	Spring Steel	nVent CADDY Armour	14 - 18 mm	8 - 14 mm	120N
812M58SM	160060	Spring Steel	nVent CADDY Armour	18 - 30 mm	8 - 14 mm	120N
6M912SM	173650	Spring Steel	nVent CADDY Armour	14 - 18 mm	14 - 20 mm	120N
812M1318SM	160145	Spring Steel	nVent CADDY Armour	18 - 30 mm	21 - 28 mm	120N
812M912SM	160070	Spring Steel	nVent CADDY Armour	18 - 30 mm	14 - 20 mm	120N
16M912SM	173740	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	14 - 20 mm	120N
20M912SM	173780	Spring Steel	nVent CADDY Armour	35 - 42 mm	14 - 20 mm	120N
24M912SM	173810	Spring Steel	nVent CADDY Armour	42 - 50 mm	14 - 20 mm	120N


CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
8M912SMS1	179670	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	14 - 20 mm	90N

Table 2/2

Catalog Number	Article Number	Certifications
12M24SMS1	179690	
16M24SM	173720	UL, cUL
20M24SM	171720	cUL, UL
24M24SM	176690	cUL, UL
32M24SM	173830	UL, cUL
6M24SM	173640	UL, cUL
812M24SM	160050	UL, ITB, cUL
8M24SMS1	179650	
12M58SMS1	179700	
16M58SM	173730	UL, cUL
20M58SM	173770	
24M58SM	173800	cUL, UL
32M58SM	173840	UL, cUL
6M58SM	171980	UL, cUL
812M58SM	160060	UL, cUL, ITB

Catalog Number	Article Number	Certifications
6M912SM	173650	
812M1318SM	160145	cUL, UL
812M912SM	160070	ITB, UL, cUL
16M912SM	173740	cUL, UL
20M912SM	173780	
24M912SM	173810	cUL, UL
8M912SMS1	179670	

DIAGRAMS

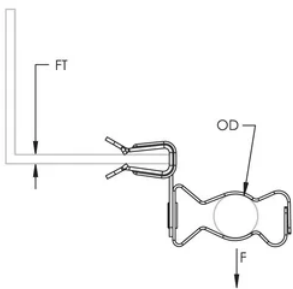

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

