

# nVent CADDY Speed Link SLK with Threaded Stud End



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polypropylene;Zinc Alloy
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)
SLK15L2SEM8	196567	1.5 mm	2m	8	45mm	55 mm


CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)
SLK15L3SEM6	196568	1.5 mm	3m	6	25mm	55 mm
SLK15L1SEM6	196564	1.5 mm	1m	6	25mm	55 mm
SLK2L5SEM8	196563	2 mm	5m	8	45mm	55 mm
SLK2L3SEM8	196561	2 mm	3m	8	45mm	55 mm
SLK2L5SEM6	196562	2 mm	5m	6	25mm	55 mm
SLK2L2SEM8	196559	2 mm	2m	8	45mm	55 mm
SLK15L1SEM8	196565	1.5 mm	1m	8	45mm	55 mm
SLK15L2SEM6	196566	1.5 mm	2m	6	25mm	55 mm
SLK15L3SEM8	196570	1.5 mm	3m	8	45mm	55 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L2SEM8	196567	19 mm	12.5 mm	90 ° Max	195N
SLK15L3SEM6	196568	19 mm	12.5 mm	90 ° Max	195N
SLK15L1SEM6	196564	19 mm	12.5 mm	90 ° Max	195N
SLK2L5SEM8	196563	19 mm	12.5 mm	90 ° Max	440N
SLK2L3SEM8	196561	19 mm	12.5 mm	90 ° Max	440N
SLK2L5SEM6	196562	19 mm	12.5 mm	90 ° Max	440N
SLK2L2SEM8	196559	19 mm	12.5 mm	90 ° Max	440N
SLK15L1SEM8	196565	19 mm	12.5 mm	90 ° Max	195N

Catalog Number	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L2SEM6	196566	19 mm	12.5 mm	90 ° Max	195N
SLK15L3SEM8	196570	19 mm	12.5 mm	90 ° Max	195N

### DIAGRAMS

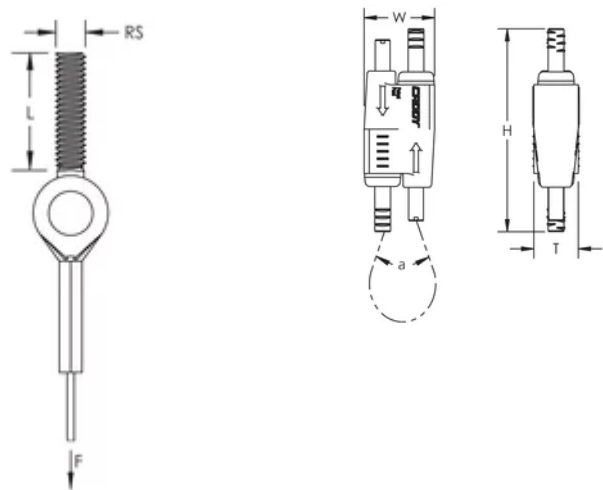

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

