

# nVent CADDY Superfix 243 M8



## CERTIFICATIONS



## FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

|                     |                       |
|---------------------|-----------------------|
| <b>Temperature:</b> | -50 to 110 °C         |
| <b>Color:</b>       | Black                 |
| <b>Finish:</b>      | Electrogalvanized     |
| <b>Material:</b>    | Steel;EPDM-SBR Rubber |

Table 1/2

| Catalog Number | Article Number | Outer Diameter (OD) | NB/DN | Rod Size (RS) | Width (W) | Thickness (T) |
|----------------|----------------|---------------------|-------|---------------|-----------|---------------|
| SXE061         | 589320         | 60 - 64 mm          | 50    | M8            | 20 mm     | 1.2 mm        |


| CatalogNumber | Article Number | Outer Diameter (OD) | NB/DN | Rod Size (RS) | Width (W) | Thickness (T) |
|---------------|----------------|---------------------|-------|---------------|-----------|---------------|
| SXE052        | 400062         | 48 - 53 mm          | 40    | M8            | 20 mm     | 1.2 mm        |
| SXE028        | 400058         | 26 - 30 mm          | 20    | M8            | 20 mm     | 1.2 mm        |
| SXE023        | 400057         | 20 - 23 mm          | 15    | M8            | 20 mm     | 1.2 mm        |
| SXE043        | 400060         | 40 - 43 mm          | 32    | M8            | 20 mm     | 1.2 mm        |
| SXE058        | 589310         | 50 - 55 mm          |       | M8            | 20 mm     | 1.2 mm        |
| SXE014        | 400055         | 12 - 16 mm          | 8     | M8            | 20 mm     | 1.2 mm        |
| SXE019        | 400056         | 15 - 19 mm          | 10    | M8            | 20 mm     | 1.2 mm        |
| SXE035        | 400059         | 31 - 36 mm          | 25    | M8            | 20 mm     | 1.2 mm        |

| Table 2/2      |                |                     |                  |             |
|----------------|----------------|---------------------|------------------|-------------|
| Catalog Number | Article Number | Screw Diameter (Sc) | Screw Length (L) | Static Load |
| SXE061         | 589320         | 5                   | 30mm             | 1300N       |
| SXE052         | 400062         | 5                   | 30mm             | 1300N       |
| SXE028         | 400058         | 5                   | 25mm             | 1000N       |
| SXE023         | 400057         | 5                   | 25mm             | 1000N       |
| SXE043         | 400060         | 5                   | 30mm             | 1000N       |
| SXE058         | 589310         | 5                   | 30mm             | 1300N       |
| SXE014         | 400055         | 5                   | 25mm             | 1000N       |
| SXE019         | 400056         | 5                   | 25mm             | 1000N       |
| SXE035         | 400059         | 5                   | 30mm             | 1000N       |

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

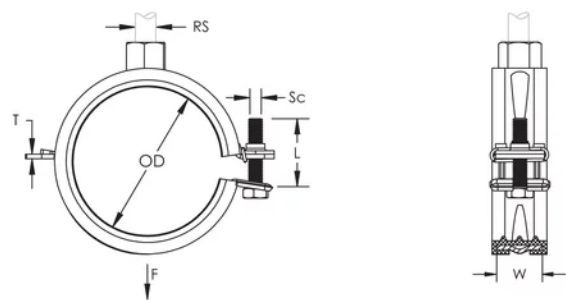

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

