

# PEMSA Wire Basket Tray Center Support



## CERTIFICATIONS



## FEATURES

Ideal for tray widths up to 200mm

Side load access for cable installation

IEC 61537 load rating and earthing compliant

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	Color	Length (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M6	820400		59mm	35 mm	5 mm	6 mm
WBTCTRSPT M10	820420		59mm	35 mm	5 mm	8 - 10 mm

CatalogNumber	Article Number	Color	Length (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPRT M10BG	820421	Black	59mm	35 mm	5 mm	8 - 10 mm

Table 2/2

Catalog Number	Article Number	Certifications
WBTCTRSPRTM6	820400	CE, CADDY EU WBT QC
WBTCTRSPRTM10	820420	CE, CADDY EU WBT QC, ANOR EU WTB EG S4 BG
WBTCTRSPRTM10BG	820421	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT QC

## DIAGRAMS

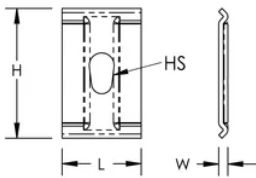

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

