

Multi-Purpose Grounding Clamp



FEATURES

Cross connector for round-to-round, round-to-tape, and tape-to-tape connections

SPECIFICATIONS



Table 1/2

Catalog Number	Article Number	Material	Finish	Conductor Size	Tape Size	Depth (D)
CCFR308	545270	Brass		8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm	56mm
CCG308	545180	Steel	Hot-Dip Galvanized	8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm	56mm
CCS-308	545170	Stainless Steel 304 (EN 1.4301)		8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm	56mm

Table 2/2

Catalog Number	Article Number	Width (W)	Unit Weight
CCFR308	545270	56 mm	0.15 kg
CCG308	545180	56 mm	0.15 kg
CCS-308	545170	56 mm	0.15 kg

DIAGRAMS

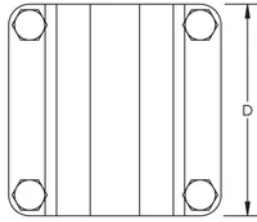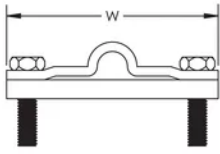

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE