


# Door Frame Mounting Profiles, DCP

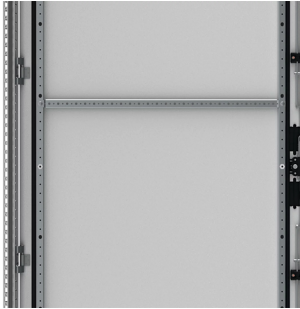

Mounting profiles are used to fit accessories to the door frame for easy and secure mounting of cables, ducts, etc.

## FEATURES

---

Description: Horizontal profiles with 25 mm hole pattern. Fits directly onto the door frame. For easy mounting of light equipment by using CNT05 screws, hole pattern of 4.5 mm and 6.5 mm in diameter.

Material: 2 mm zinc plated steel.

Pack quantity: 20 bars with mounting accessories.

## SPECIFICATIONS

**Thickness:** 2mm  
**Material:** Mild Steel  
**Finish:** Zinc Plated

Table 1/1

| Catalog Number | Article Number | Height | Width | Depth | Enclosure Material | Product Family |
|----------------|----------------|--------|-------|-------|--------------------|----------------|
| DCP402         | DCP402         | 24mm   | 392mm | 14mm  | Mild Steel         | Free-Standing  |
| DCP1002        | DCP1002        | 24mm   | 992mm | 14mm  | Mild Steel         | Free-Standing  |
| DCP602         | DCP602         | 24mm   | 592mm | 14mm  | Mild Steel         | Free-Standing  |
| DCP802         | DCP802         | 24mm   | 792mm | 14mm  | Mild Steel         | Free-Standing  |
| DCP502         | DCP502         | 24mm   | 492mm | 14mm  | Mild Steel         | Free-Standing  |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**