

# H-MSMR Conduit to Flange Clip with Retainer, Side Mount



## FEATURES

Only one piece to install

Fast hammer-on installation

Pre-riveted retainer strap is easily bent into position

Lightweight design

## SPECIFICATIONS

**Finish:** nVent CADDY Armour


**Material:** Spring Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Flange Thickness (FT)	Length (L)	Static Load
C2416SM	23.4 - 35 mm	3.2 - 6.4 mm	330.2mm	120N
C24812SM	18 - 30 mm	3.2 - 6.4 mm	199mm	120N
C5816SM	23.4 - 35 mm	7.9 - 12.7 mm	330.2mm	120N
C58812SM	18 - 30 mm	7.9 - 12.7 mm	199mm	120N

Catalog Number	Outer Diameter (OD)	Flange Thickness (FT)	Length (L)	Static Load
C912812SM	18 - 30 mm	14.3 - 19.1 mm	199mm	120N
C91216SM	23.4 - 35 mm	14.3 - 19.1 mm	330.2mm	120N

### DIAGRAMS

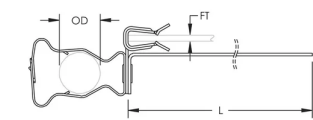

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

