

# nVent CADDY Slick Nut



## FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

Table 1/2

Catalog Number	Article Number	Material	Hole Size (HS)	Hole Type	Height (H)	Torque (TQ)
SLICK250		Polyamide, Spring Steel	0.25 mm	Threaded	17 mm	5 N·m
SLICKM6	174460	Spring Steel	6 mm	Threaded	17 mm	6 N·m
SLICKM8	174340	Spring Steel	8 mm	Threaded	17 mm	8 N·m

Table 2/2


Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
SLICK250		1800N	450N	1100N
SLICKM6	174460	1800N	450N	1100N
SLICKM8	174340	2700N	450N	1100N

ADDITIONAL PRODUCT DETAILS

Indicated loads are independent of the threaded stud or rod.

Indicated loads are applicable on 14 GA and 12 GA (2 mm and 2.5 mm) strut channels only.

DIAGRAMS

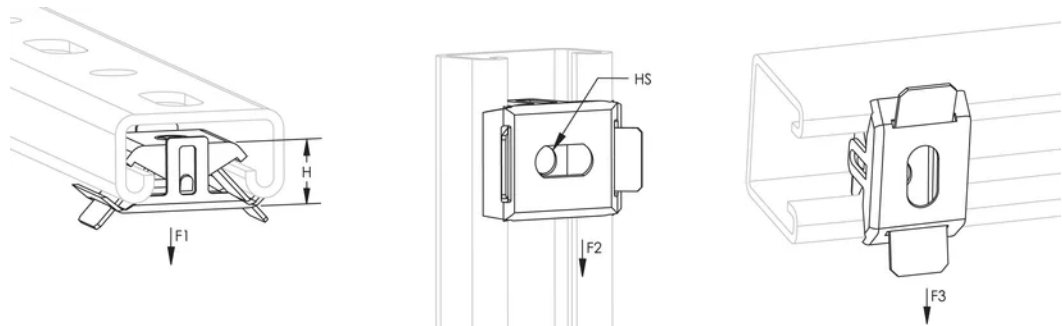

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

