


nVent CADDY Cat HP J-Hook Clip to BC200 Beam Clamp, Swivel

Data Solutions



CERTIFICATIONS

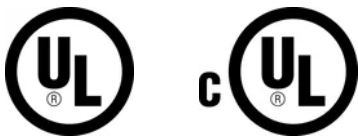

FEATURES

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook


SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Static Load
----------------	----------------	----------	--------	-----------------------	-------------

CATHPBC200B	181074	Steel, Spring Steel	Electrogalvanized, nVent CADDY Armour	3.2 – 16mm	440N
-------------	--------	---------------------	---	------------	------

DIAGRAMS

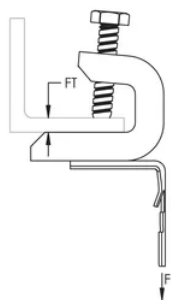

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY
ERICO
HOFFMAN
ILSCO
SCHROFF
TRACHTE