



Cast Secondary Bonding Lug

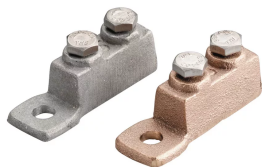

CERTIFICATIONS

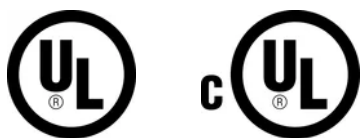

FEATURES

Cast terminal bonding lug with two bolt tension on secondary conductors

Use to connect metal objects such as ladders and drains to lightning protection system

SPECIFICATIONS

Conductor Size, UL: Secondary

Table 1/2

Catalog Number	Material	Finish	Hole Size (HS)	Depth (D)	Height (H)	Width (W)
LPA555	Aluminum	Bare	7.9 mm	19.05mm	19.8 mm	60.33 mm
LPC555L	Brass	Tinned	7.9 mm	19.05mm	19.8 mm	60.33 mm
LPC555	Brass	Bare	7.9 mm	19.05mm	19.8 mm	60.33 mm


Table 2/2

Catalog Number	Unit Weight	Certifications
LPA555	0.04 kg	
LPC555L	0.1 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC555	0.1 kg	E202878-Combined_CoC, E202878-Combined_CoC

ADDITIONAL PRODUCT DETAILS

For use with secondary bonding cables and wires up to 0.3" (7.62 mm) in diameter.

DIAGRAMS

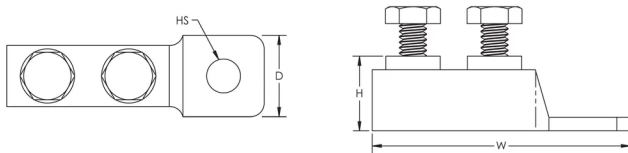

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ **WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE